


# Axygen® Pipet Tips

10 µL, 20 µL, 200 µL, 300 µL, 1,000 µL

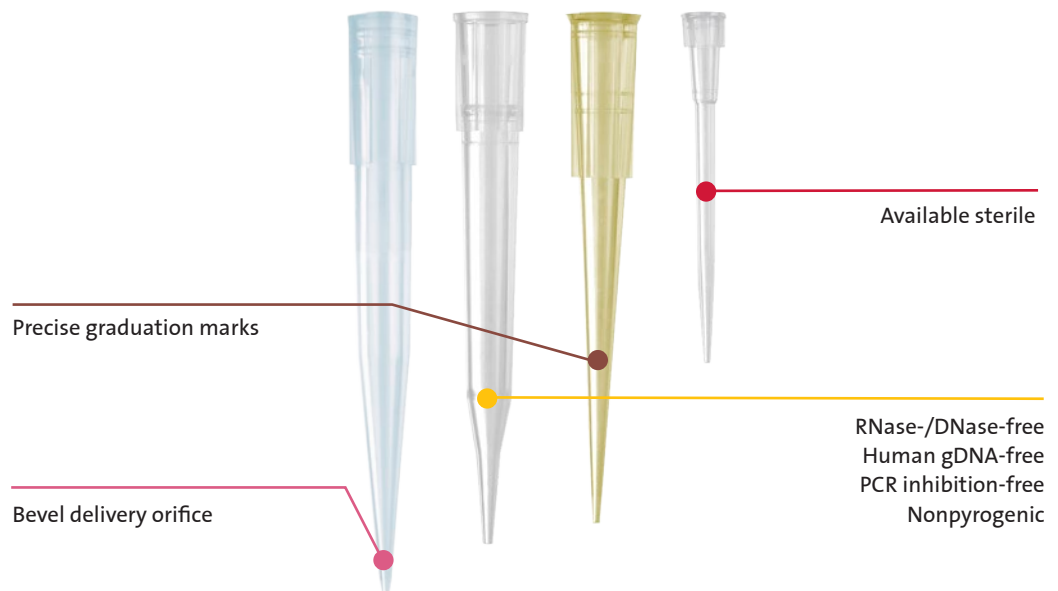

Cat. No.	Description	Quantity
T-1000-B-R	1,000 µL Pipet tips, blue, universal fit, beveled, racked	100/rack, 10 racks/pk, 5 pk/cs
T-1000-B-R-S	1,000 µL Pipet tips, blue, universal fit, beveled, racked, sterile	100/rack, 10 racks/pk, 5 pk/cs
T-1000-C-R	1,000 µL Pipet tips, clear, universal fit, beveled, racked	100/rack, 10 racks/pk, 5 pk/cs
T-1000-C-R-S	1,000 µL Pipet tips, clear, universal fit, beveled, racked, sterile	100/rack, 10 racks/pk, 5 pk/cs
T-350-C-R	300 µL Pipet tips, clear, universal fit, fine point, racked	96/rack, 10 racks/pk, 5 pk/cs
T-350-C-R-S	300 µL Pipet tips, clear, universal fit, fine point, racked, sterile	96/rack, 10 racks/pk, 5 pk/cs
T-200-Y-R	200 µL Pipet tips, yellow, universal fit, beveled, racked	96/rack, 10 racks/pk, 5 pk/cs
T-200-Y-R-S	200 µL Pipet tips, yellow, universal fit, beveled, racked sterile	96/rack, 10 racks/pk, 5 pk/cs
T-200-C-R	200 µL Pipet tips, clear, universal fit, beveled, racked	96/rack, 10 racks/pk, 5 pk/cs
T-200-C-R-S	200 µL Pipet tips, clear, universal fit, beveled, racked, sterile	96/rack, 10 racks/pk, 5 pk/cs
T-400-R	20 µL (0.5-20) µL Pipet tips, clear, ultra micro, racked (Eppendorf compatible)	96/rack, 10 racks/pk, 5 pk/cs
T-400-R-S	20 µL (0.5-20 µL) Pipet tips, clear, ultra micro, racked, sterile (Eppendorf compatible)	96/rack, 10 racks/pk, 5 pk/cs
T-300-R	10 µL (0.5-10 µL) Pipet tips, clear, microvolume, racked	96/rack, 10 racks/pk, 5 pk/cs
T-300-R-S	10 µL (0.5-10 µL) Pipet tips, clear, microvolume, racked, sterile	96/rack, 10 racks/pk, 5 pk/cs
TXL-10-R	10 µL (0.1-20 µL) Pipet tips, clear, microvolume, extended, racked	96/rack, 10 racks/pk, 5 pk/cs
TXL-10-R-S	10 µL (0.1-20 µL) Pipet tips, clear, microvolume, extended, racked, sterile	96/rack, 10 racks/pk, 5 pk/cs

Continued on back

## Bulk Packed

Cat. No.	Description	Quantity
T-1000-B	1,000 µL Pipet tips, blue, universal fit, beveled, bulk	1,000/pk, 5 pk/cs
T-1000-C	1,000 µL Pipet tips, clear, universal fit, beveled, bulk	1,000/pk, 5 pk/cs
T-350-C	300 µL Pipet tips, universal fit, fine point, bulk	1,000/pk, 10 pk/cs
T-200-Y	200 µL Pipet tips, yellow, universal fit, beveled, bulk	1,000/pk, 20 pk/cs
T-200-C	200 µL Pipet tips, clear, universal fit, beveled, bulk	1,000/pk, 20 pk/cs
T-400	20 µL (0.5-20 µL) Pipet tips, clear, ultra micro, bulk (Eppendorf compatible)	1,000/pk, 20 pk/cs
T-300	10 µL (0.5-10 µL) Pipet tips, clear, microvolume, bulk	1,000/pk, 20 pk/cs
TXL-10	10 µL (0.1-20 µL) Pipet tips, clear, microvolume, extended, bulk	1,000/pk, 20 pk/cs

For more specific information on claims, visit the Certificates page at [www.corning.com/lifesciences](http://www.corning.com/lifesciences).

**Warranty/Disclaimer:** Unless otherwise specified, all products are for research use only. Not intended for use in diagnostic or therapeutic procedures. Corning Life Sciences makes no claims regarding the performance of these products for clinical or diagnostic applications.

For additional product or technical information, visit [www.corning.com/lifesciences](http://www.corning.com/lifesciences) or call 800.492.1110. Customers outside the United States, call +1.978.442.2200 or contact your local Corning sales office.

### Corning Incorporated Life Sciences

836 North St.  
Building 300, Suite 3401  
Tewksbury, MA 01876  
t 800.492.1110  
t 978.442.2200  
f 978.442.2476  
[www.corning.com/lifesciences](http://www.corning.com/lifesciences)

### Worldwide Support Offices

#### ASIA/PACIFIC

**Australia/New Zealand**  
t 61 427286832

**China**  
t 86 21 3338 4338  
f 86 21 3338 4300

**India**  
t 91 124 4604000  
f 91 124 4604099

#### Japan

t 81 3-3586 1996  
f 81 3-3586 1291

#### Korea

t 82 2-796-9500  
f 82 2-796-9300

#### Singapore

t 65 6572-9740  
f 65 6861-2913

#### Taiwan

t 886 2-2716-0338  
f 886 2-2516-7500

### EUROPE

#### France

t 0800 916 882  
f 0800 918 636

#### Germany

t 0800 101 1153  
f 0800 101 2427

#### The Netherlands

t 020 655 79 28  
f 020 659 76 73

#### United Kingdom

t 0800 376 8660  
f 0800 279 1117

### All Other European Countries

t 31 (0) 20 659 60 51  
f 31 (0) 20 659 76 73

### LATIN AMERICA

grupoLA@corning.com

**Brasil**  
t (55-11) 3089-7400

**Mexico**  
t (52-81) 8158-8400

**CORNING** | **FALCON** | **AXYGEN** | **GOSELIN** | **PYREX**

For a listing of trademarks, visit [www.corning.com/clstrademarks](http://www.corning.com/clstrademarks).  
All other trademarks are the property of their respective owners.