

Corning® Bottle Top Dispensers

Safe and Precise Dispensing with No Loss of Reagent

CORNING

The Corning Bottle Top Dispenser is a universal solution for dispensing organic and inorganic liquids. The specialized air-purging and closed circuit system ensures no loss of reagent during dispensing, as well as when the device is not in use.


The dispenser comes with 4 adapters with different diameters for universal use with multiple bottle sizes. The telescopic suction tube can be adjusted smoothly to different bottle heights. The calibration tool allows easy in-lab calibration with a built-in recalibration mechanism to ensure the highest reproducibility during the dispenser's long life cycle. Every dispenser is individually tested and delivered with a certificate of performance.

Corning Bottle Top Dispensers are suitable for using with a wide range of chemical solutions. The components that come directly in contact with the reagents are made of chemical resistant, robust materials such as platinum, ceramic, PTFE, or borosilicate glass.

Features and Benefits

- ▶ Six (6) different volume models to dispense solutions from 0.25 to 100 mL
- ▶ Easy in-lab calibration with built-in recalibration mechanism
- ▶ Accurate and reproducible volume setting with quick volume lock knob*
- ▶ Fully autoclavable for protection against contamination
- ▶ 360° rotatable valve block for convenient dispensing with tough bottle connections
- ▶ Convenient 3-position discharge tube for dispensing, sample recovery, and emptying
- ▶ Unique drip-free system for your safety at work
- ▶ Easy disassembly for cleaning

*100 mL dispenser comes with volume adjustment screw

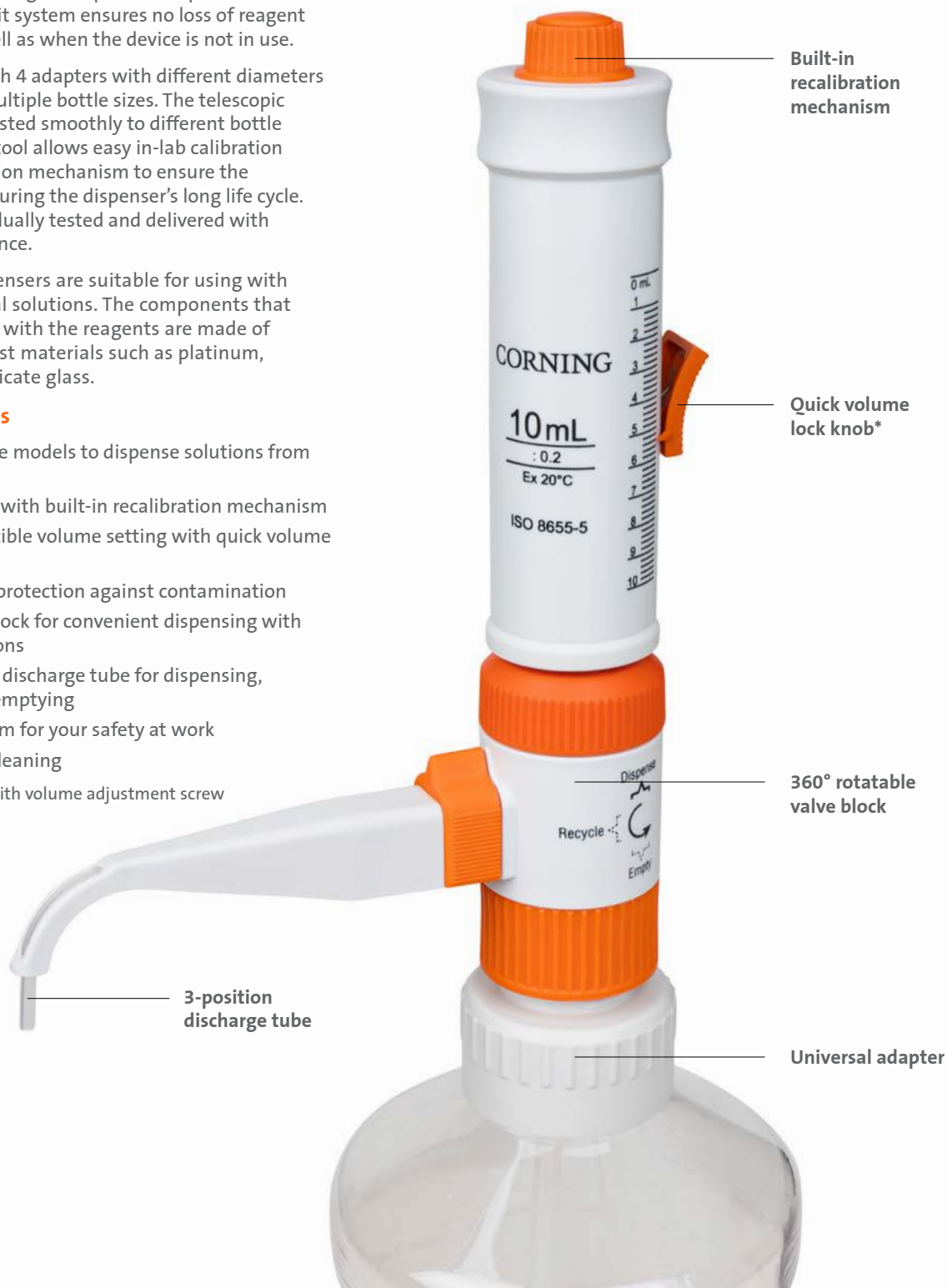

Ordering Information



Corning® Bottle Top Dispensers

Cat. No.	Volume Range	Thread Size	Qty/Cs
6840	0.25 - 2.5 mL	GL 32	1
6841	0.5 - 5 mL	GL 32	1
6842	1 - 10 mL	GL 32	1
6843	2.5 - 25 mL	GL 45	1
6844	5 - 50 mL	GL 45	1
6845	10 - 100 mL	GL 45	1

Telescopic Suction Tubes

Cat. No.	Description	Qty/Cs
6867	2.5 - 10 mL	1
6868	25 - 100 mL	1

Borosilicate Glass Accessories

6869	One-way valve	1
6870	Calcium chloride tube	1

Thread Adapters Made of PP

Cat. No.	Description	Qty/Cs
6871	A32/A25	1
6872	A32/A28	1
6873	A32/A38	1
6874	A32/A40	1
6875	A32/A45	1
6876	A45/A32	1

Related Products

PYREX® Round Media Storage Bottles



Cat. No.	Capacity (mL)	Thread	Approx. Diameter x Height (mm)	Grad. Range (mL)	Grad. Interval (mL)	Qty/Cs
1395-25	25	GL 25	36.5 x 70	10-25	5	10
1395-50	50	GL 32	46 x 88	20-50	10	10
1395-100	100	GL 45	56 x 100	40-80	20	10

Corning Polystyrene (PS) Storage Bottles



Cat. No.	Capacity (mL)	Neck Diameter (mm)	Shape	Qty/Pk	Qty/Cs
431175	150	45	Easy Grip Round	2	24
430281	250	45	Easy Grip Round	2	24
430282	500	45	Easy Grip Round	2	24
430518	1,000	45	Easy Grip Round	2	24
8388	125	45	Round	1	24
8390	250	45	Round	1	12
8393	500	45	Round	1	12
8396	1,000	45	Round	1	12



Corning PET Storage Bottles



Cat. No.	Capacity (mL)	Thread	Neck I.D. Size (mm)	Approx. Diameter x Height (mm)	Grad. Range (mL)	Grad. Interval (mL)	Qty/Pk	Qty/Cs
431530	125	GL 45	37	52.5 x 106.5	50 - 125	25	12	24
431531	250	GL 45	37	59 x 142.5	50 - 250	25	12	24
431532	500	GL 45	37	77 x 176	100 - 500	50	12	24
431533	1,000	GL 45	37	92 x 216.5	100 - 1,000	50	12	24

For more specific information on claims, visit the Certificates page at www.corning.com/lifesciences.

Warranty/Disclaimer: Unless otherwise specified, all products are for research use only. Not intended for use in diagnostic or therapeutic procedures. Corning Life Sciences makes no claims regarding the performance of these products for clinical or diagnostic applications.

For additional product or technical information, visit www.corning.com/lifesciences or call 800.492.1110. Outside the United States, call +1.978.442.2200 or contact your local Corning sales office.

CORNING

Corning Incorporated
Life Sciences

836 North St.
Building 300, Suite 3401
Tewksbury, MA 01876
t 800.492.1110
t 978.442.2200
f 978.442.2476

www.corning.com/lifesciences

ASIA/PACIFIC
Australia/New Zealand
t 61 427286832

Chinese Mainland
t 86 21 3338 4338
f 86 21 3338 4300

India
t 91 124 4604000
f 91 124 4604099

Japan
t 81 3-3586 1996
f 81 3-3586 1291

Korea
t 82 2-796-9500
f 82 2-796-9300

Singapore
t 65 6572-9740
f 65 6735-2913

Taiwan
t 886 2-2716-0338
f 886 2-2516-7500

EUROPE
CSEurope@corning.com

France
t 0800 916 882
f 0800 918 636

Germany
t 0800 101 1153
f 0800 101 2427

The Netherlands
t 020 655 79 28
f 020 659 76 73

United Kingdom
t 0800 376 8660
f 0800 279 1117

All Other European Countries
t +31 (0) 206 59 60 51
f +31 (0) 206 59 76 73

LATIN AMERICA
grupoLA@corning.com

Brazil
t 55 (11) 3089-7400

Mexico
t (52-81) 8158-8400